


MODLINK MSDD DBL COMBI INSERT USA 2XNEMA 5-15

GFCI+1x3A fuse

2× NEMA-GFCI 5-15 (screw terminals)  
1× fuse (3 A)  
with touch protection

Link to Product

Illustration

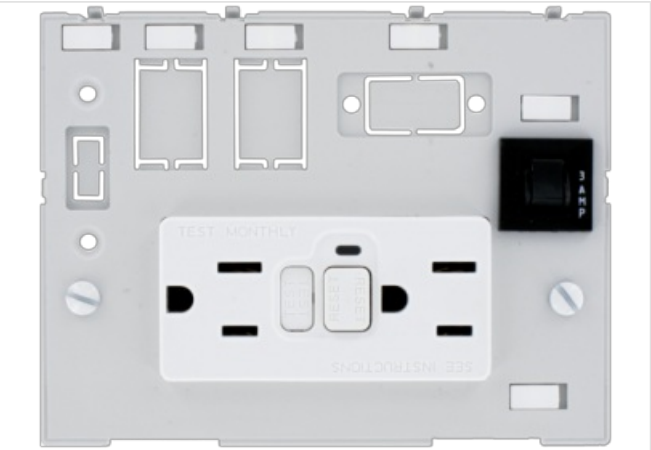

Product may differ from Image



Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879369299
Packaging unit	1
Mechanical data   Mounting data	
Height	88 mm
Width	116 mm
Depth	72 mm
Environmental characteristics   Climatic	
Storage temperature min.	-40 °C
Storage temperature max.	70 °C
Fuse	
Operating voltage AC	250 V

Operating voltage DC	32 V
Nominal current	3 A
<b>USA</b>	
Connection cross section max.	6 mm <sup>2</sup>
AWG number max.	10
Operating voltage AC	125 V
Operating current	15 A
Connection	Screw terminals SK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes