

MODLINK MSDD DBL COMBI INSERT FRANCE


RCD opening

1× France (UTE-NF) white

1× FI cut-out

Link to Product

Illustration

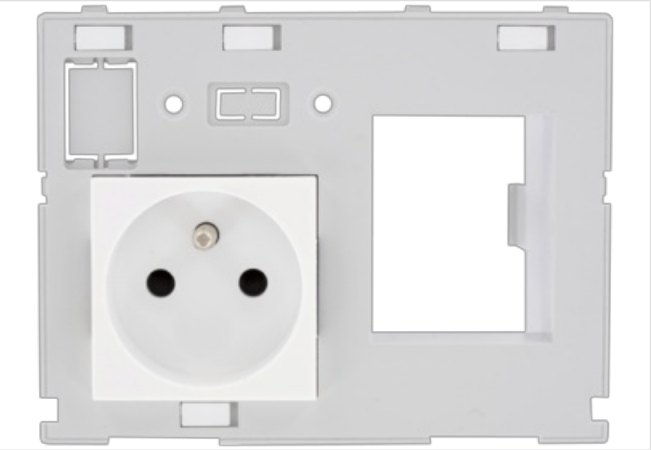

Product may differ from Image



Commercial data

ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879401876
Packaging unit	1

Mechanical data | Mounting data

Height	88 mm
Width	116 mm
Depth	70 mm

Environmental characteristics | Climatic

Storage temperature min.	-10 °C
Storage temperature max.	60 °C

Shielding plate

Connection information	Threaded hole M4
------------------------	------------------

Tightening torque 0,9 Nm

France (UTE-NF)	
Connection cross section max.	4 mm²
AWG number max.	12
Operating voltage AC	250 V
Operating current	16 A
Connection	Screw terminals SK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes