


MODLINK MSDD DBL COMBI INSERT AUMALERIALIA

RCD opening

- 1× Australia
- 1× FI cut-out

Link to Product

Illustration

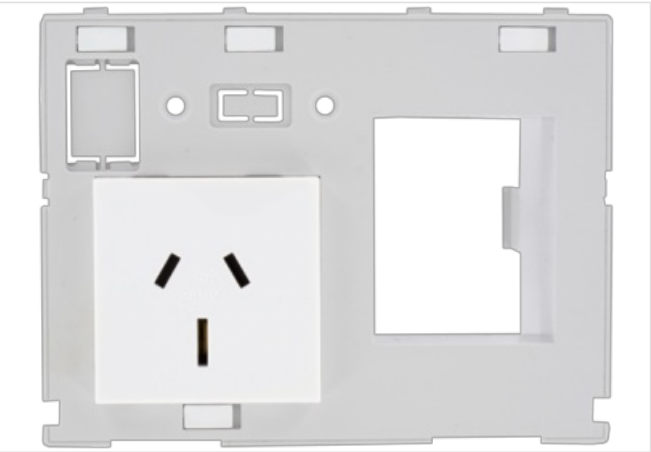

Product may differ from Image



Commercial data

ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879405850
Packaging unit	1

Mechanical data | Mounting data

Height	88 mm
Width	116 mm
Depth	70 mm

Environmental characteristics | Climatic

Storage temperature min.	-10 °C
Storage temperature max.	70 °C

Australia

Connection cross section max.	4 mm²
AWG number max.	12

Operating voltage AC	240 V
Operating current	15 A
Connection	Screw terminals SK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes