



MODLINK MSDD FRAME DBL METAL

Nickeled

Frame: metal, matte nickel plated
Lid: metal, matte nickel plated

[Link to Product](#)

Illustration

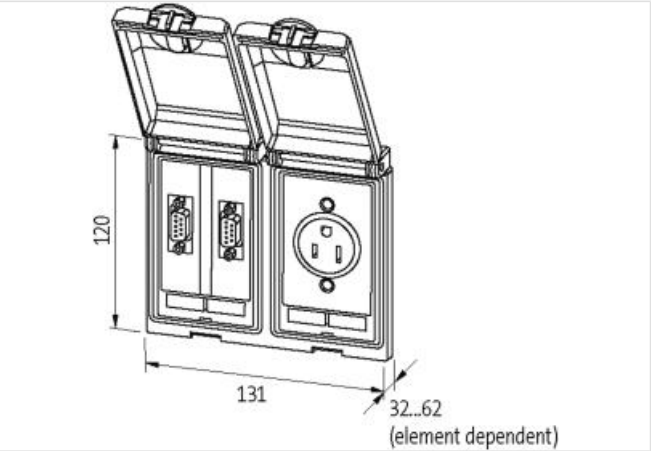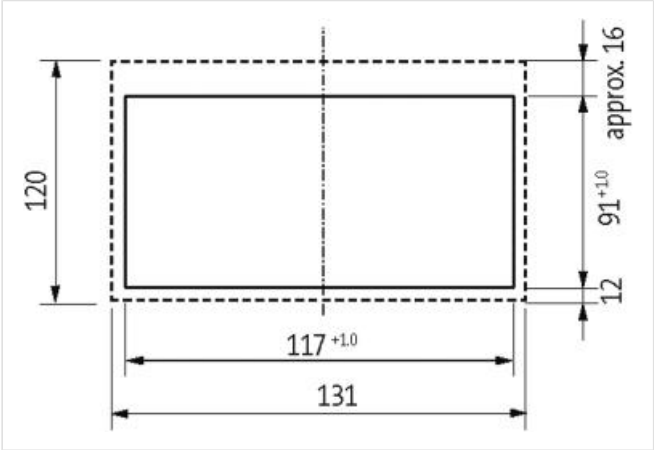

Product may differ from Image



Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27189260
ECLASS-7.0	27189260
ECLASS-8.0	27189260
ECLASS-9.0	27189260
ECLASS-10.1	27182810
ECLASS-11.1	27182810
ECLASS-12.0	27182810

ETIM-5.0	EC002625
customs tariff number	85389099
GTIN	4048879035286
Packaging unit	1

Device protection

Shielded	yes
----------	-----

Mechanical data | Mounting data

Height	120 mm
Width	130 mm
Depth	35 mm

Frame

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-10 °C
Operating temperature max.	60 °C
Storage temperature min.	-25 °C
Storage temperature max.	60 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Coating housing	surface finished
Material housing	Fine zinc die casting