



MODLINK MSDD FRAME SINGLE GRAY

Closure 3 mm double bit incl. pluggable knob

Frame: plastic PA black
Lid: plastic, PBT gray
Closure: 3 mm double bit
with attachable rotation knob

Link to Product

Illustration

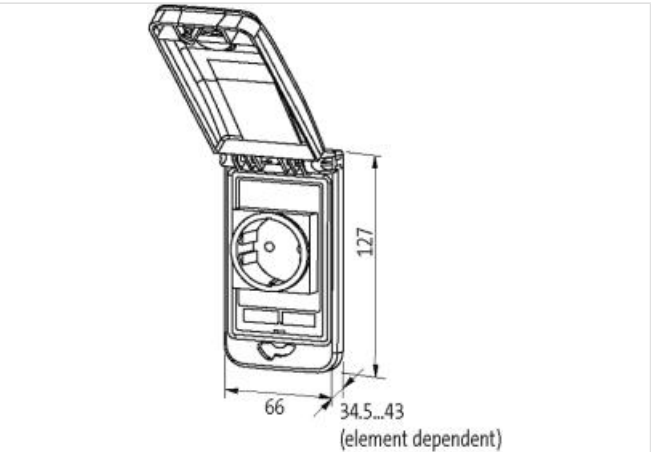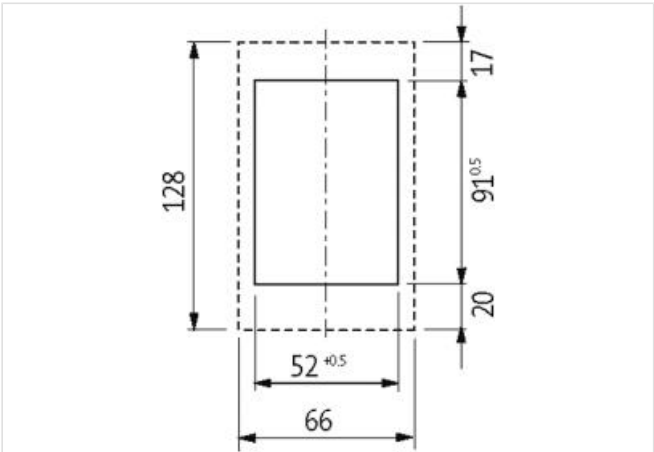

Product may differ from Image



| Commercial data | |
|-----------------|----------|
| ECLASS-6.0 | 27189217 |
| ECLASS-6.1 | 27189260 |
| ECLASS-7.0 | 27189260 |
| ECLASS-8.0 | 27189260 |
| ECLASS-9.0 | 27189260 |
| ECLASS-10.1 | 27182810 |

| | |
|-----------------------|---------------|
| ECLASS-11.1 | 27182810 |
| ECLASS-12.0 | 27182810 |
| ETIM-5.0 | EC002625 |
| customs tariff number | 85389099 |
| GTIN | 4048879368841 |
| Packaging unit | 1 |

Mechanical data | Mounting data

| | |
|--------|--------|
| Height | 127 mm |
| Width | 66 mm |
| Depth | 43 mm |

Frame

| | |
|---|--------|
| Degree of protection (EN IEC 60529) | IP65 |
| Operating temperature min. | -30 °C |
| Operating temperature max. | 70 °C |
| Storage temperature min. | -30 °C |
| Storage temperature max. | 80 °C |
| Suitable for installation wall thickness min. | 1 mm |
| Suitable for installation wall thickness max. | 5 mm |
| Color cover | gray |
| Color housing | black |
| Material lid | PBT |
| Material housing | PA |