



MODLINK MSDD FRAME DBL TRANSPARENT

Closure Daimler

Frame: plastic PA black  
Lid: plastic, PC transparent  
Closure: Daimler

Link to Product

Illustration

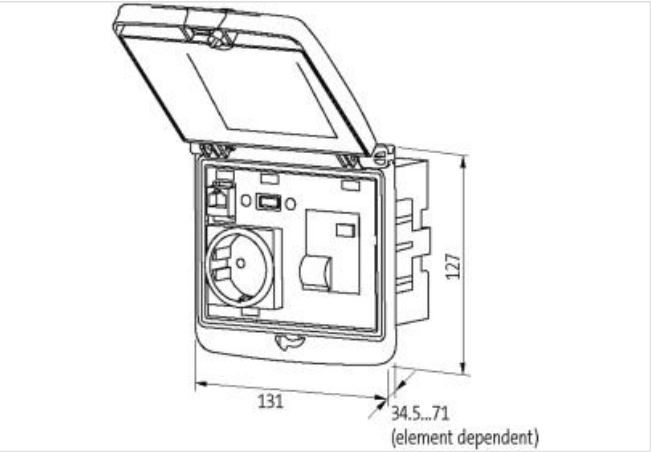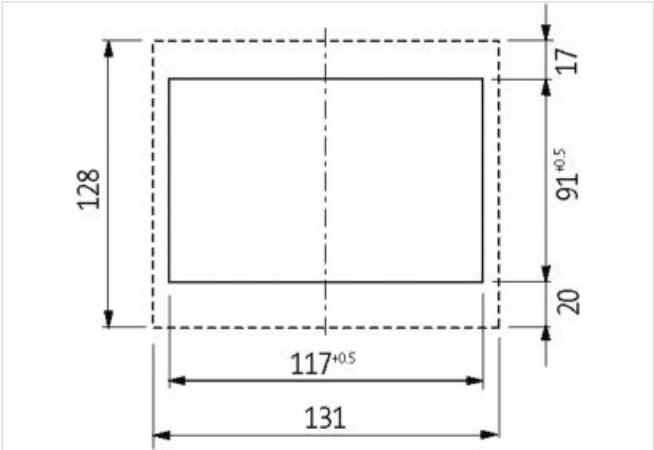

Product may differ from Image



Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27189260
ECLASS-7.0	27189260
ECLASS-8.0	27189260
ECLASS-9.0	27189260
ECLASS-10.1	27182810

ECLASS-11.1	27182810
ECLASS-12.0	27182810
ETIM-5.0	EC002625
customs tariff number	85389099
GTIN	4048879388733
Packaging unit	1

**Mechanical data | Mounting data**

Height	127 mm
Width	66 mm
Depth	43 mm

**Frame**

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Color cover	transparent
Color housing	black
Material lid	PC
Material housing	PA