

MODLINK MPV CONTROL CABINET COUPLING

MPV Frame


Double (30°-angle)  
for standard cut-out  
Size 24 (35×112 mm)  
IP65

Link to Product

Illustration



Product may differ from Image

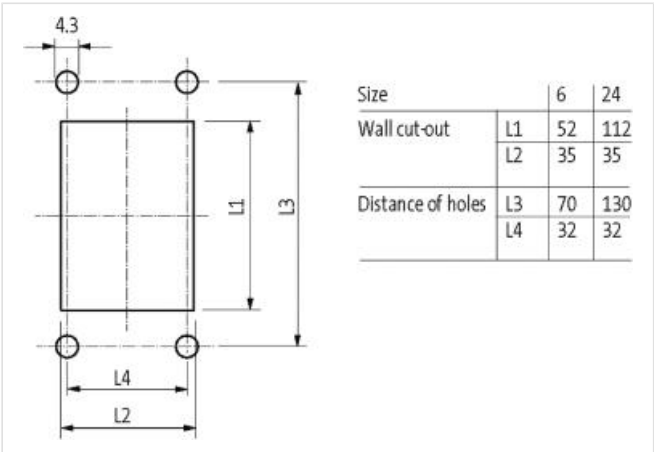

Commercial data

ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27189217
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC002625
customs tariff number	85389099
GTIN	4048879032186
Packaging unit	1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Mechanical data | Material data

Material housing	PBT
------------------	-----

Mechanical data | Mounting data

Height	151 mm
Width	58 mm
Depth	28 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-25 °C
Operating temperature max.	80 °C