

MODLINK MSVD CABINET POWER OUTLETS

Switzerland 250V AC / 10 A


Swiss (white)
Spring clamp terminals

Link to Product

Illustration



Product may differ from Image

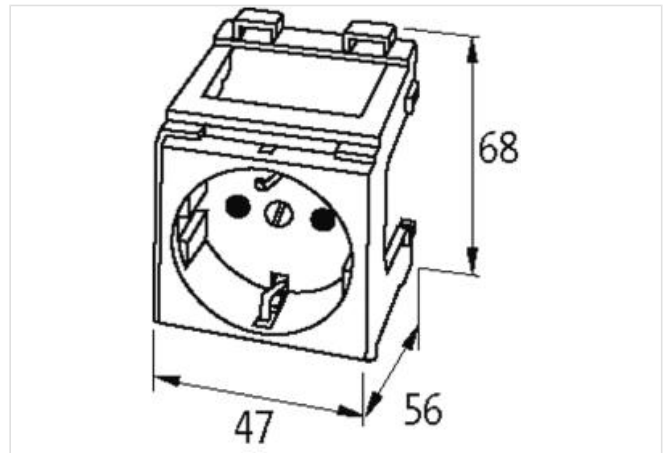

Commercial data

ECLASS-6.0	27143423
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC002625
customs tariff number	85366990
GTIN	4048879031295
Packaging unit	1

Electrical data | Supply

Operating voltage AC	250 V
Operating current	10 A

Installation

Connection cross section max.	1,5 mm²
AWG number	16

Installation | Connection

Connection	Spring clamp plug-in terminals
------------	--------------------------------

Mechanical data | Mounting data

The information in this Product-PDF has been compiled with the utmost care.
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2024-05-04

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	68 mm
Width	47 mm
Depth	56 mm