

CHINA SOCKET MODULE


China (white)
Screw terminals

Link to Product

Illustration



Product may differ from Image

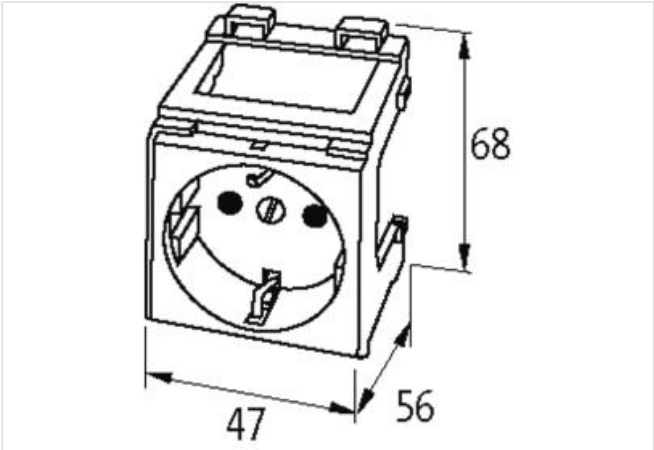

Commercial data	
ECLASS-6.0	27143423
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879031196
Packaging unit	1
Electrical data Supply	
Operating voltage AC	250 V
Operating current	10 A
Installation	
Connection cross section max.	4 mm²
AWG number	12
Installation Connection	
Connection	Screw terminals SK
Mechanical data Mounting data	
Mounting method	geschnappt

Suitable for mounting type	mounting rail, (EN 60715)
Height	68 mm
Width	47 mm
Depth	57 mm