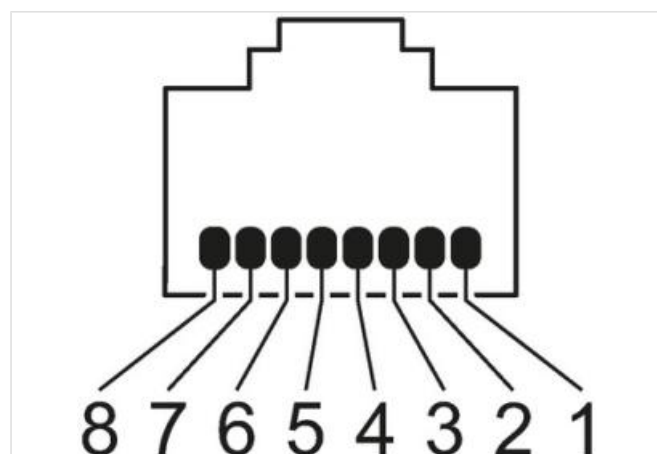
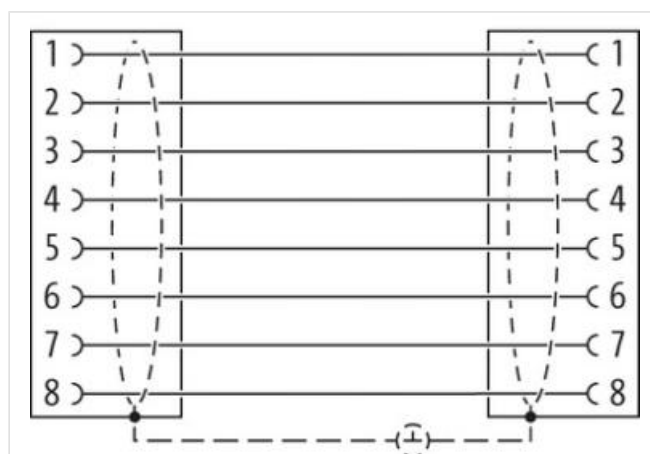
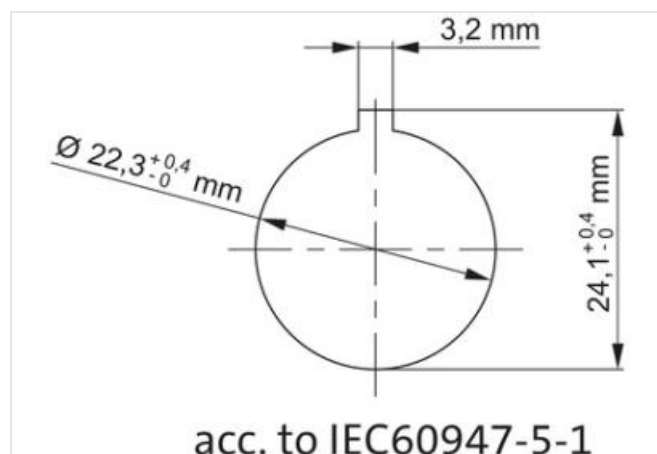
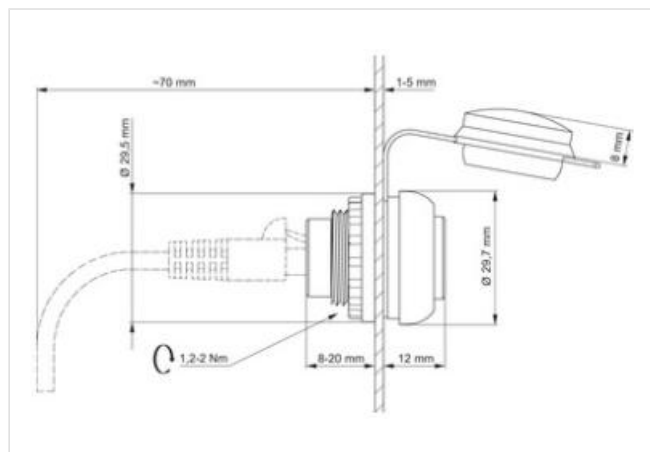
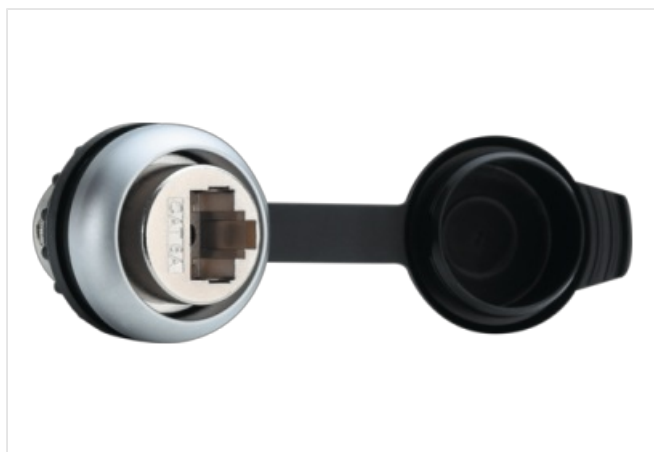



**MSDD pass-through RJ45 CAT6A femal/femal, design silver**

Pass-through

1 × RJ45, 8-pole metal, CAT6A (female/female)

[Link to Product](#)
**Illustration**


Product may differ from Image

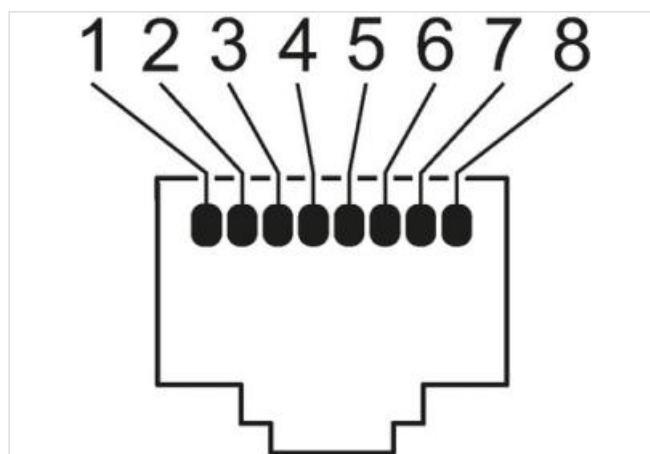



#### Commercial data

ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
customs tariff number	85366990
GTIN	4065909037256
Packaging unit	1

#### Electrical data | Supply

Operating voltage AC	24 V
Operating voltage DC	24 V
Operating current max.	1,5 A

#### Installation | Connection

Family construction form	RJ45
Gender	female
Gender Rear	female
Cable category min.	Cat6a

#### Device protection

Shielded	yes
----------	-----

#### Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state

#### Device protection | Mechanical

Mechanical endurance	750 Cycles
----------------------	------------

#### Mechanical data | Mounting data

Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	20 mm

#### Approvals

UL 50E	yes
--------	-----