
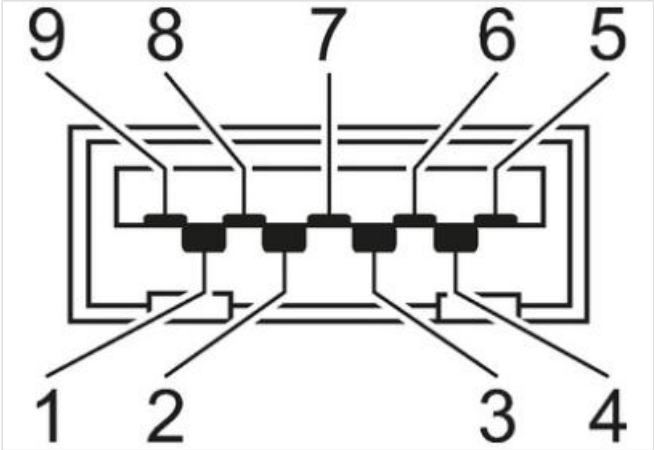
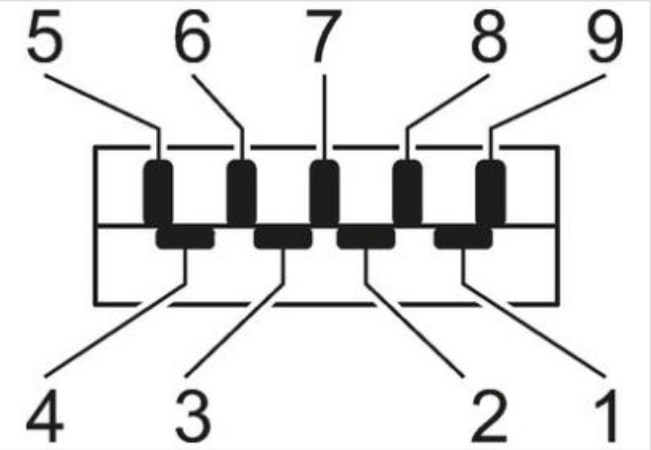
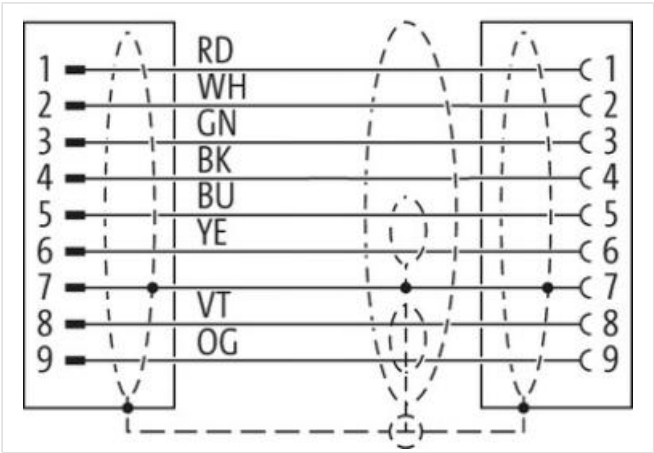
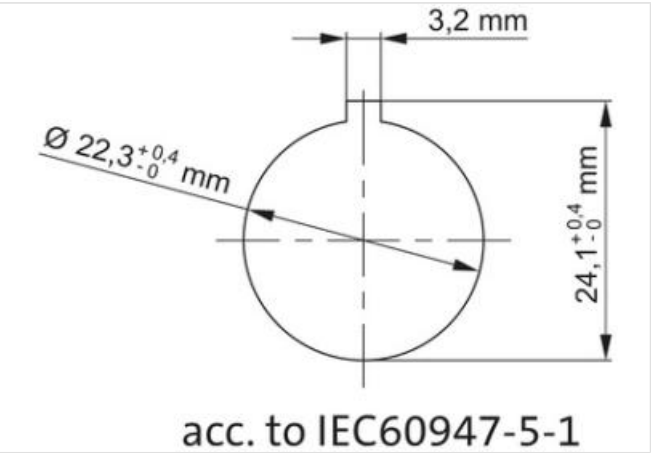


MSDD pass-through USB 3.0 form A, 2.0 m cable, design silver

Pass-through  
1 × USB 3.0 (female/male/2.0 m cable) form A

Link to Product

Illustration

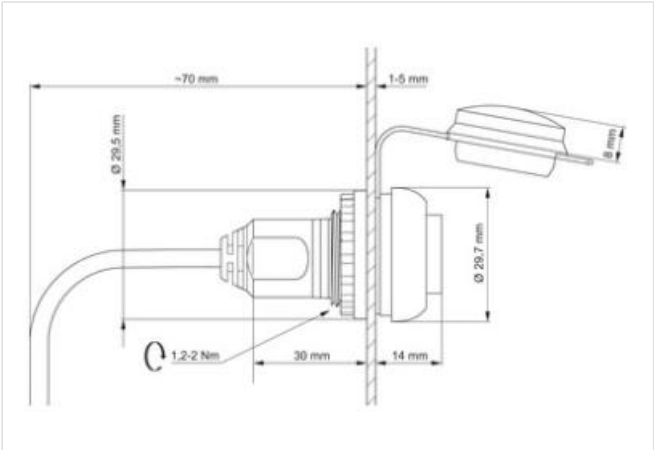

Product may differ from Image

**Commercial data**

ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
customs tariff number	85444290
GTIN	4048879433426
Packaging unit	1

**Electrical data | Supply**

Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA

**Industrial communication**

USB specification	3.0
-------------------	-----

**Device protection**

Shielded	yes
----------	-----

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state

**Device protection | Mechanical**

Mechanical endurance	1500 Cycles
----------------------	-------------

**Mechanical data | Mounting data**

Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	30 mm

**Approvals**

UL 50E	yes
--------	-----