
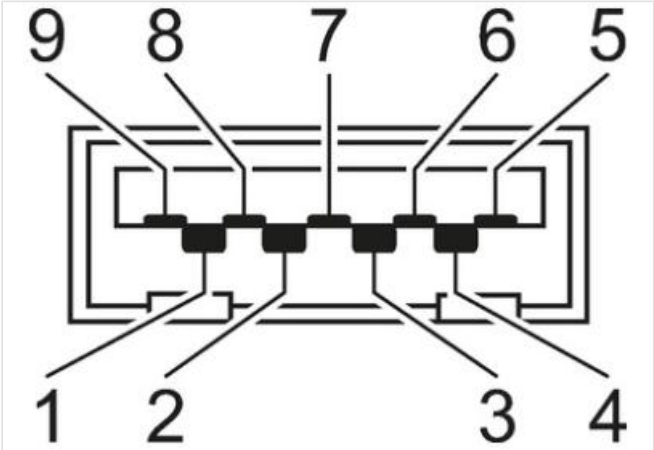
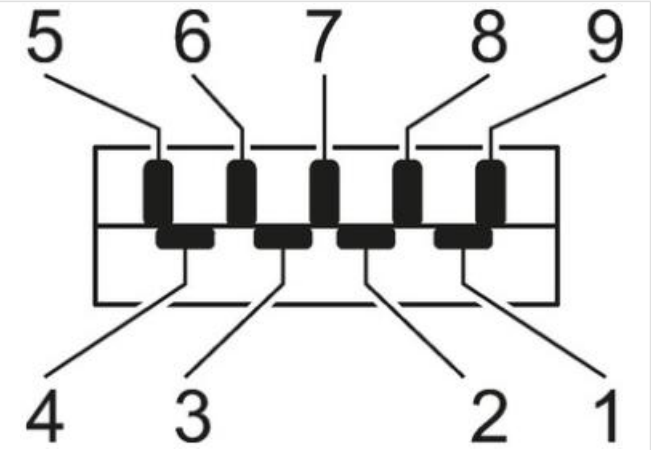
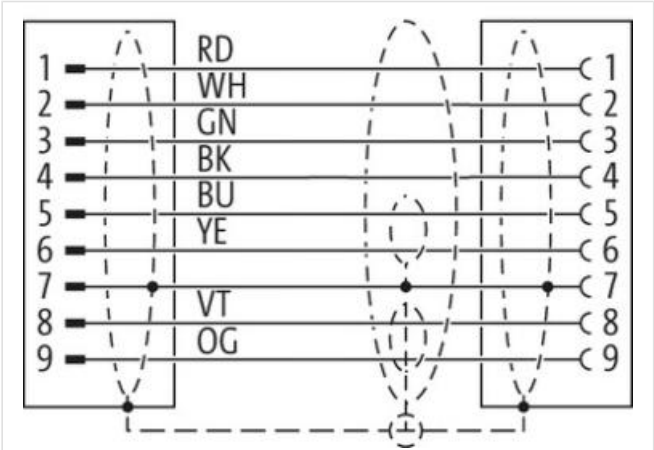
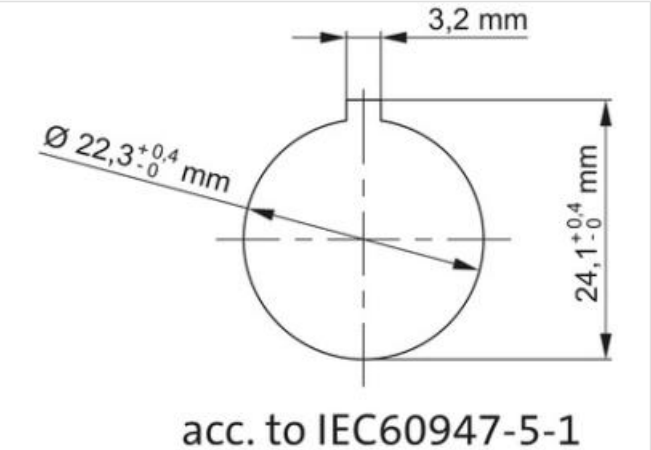


MSDD pass-through USB 3.0 form A, 5.0 m cable, design silver

[Link to Product](#)

Illustration

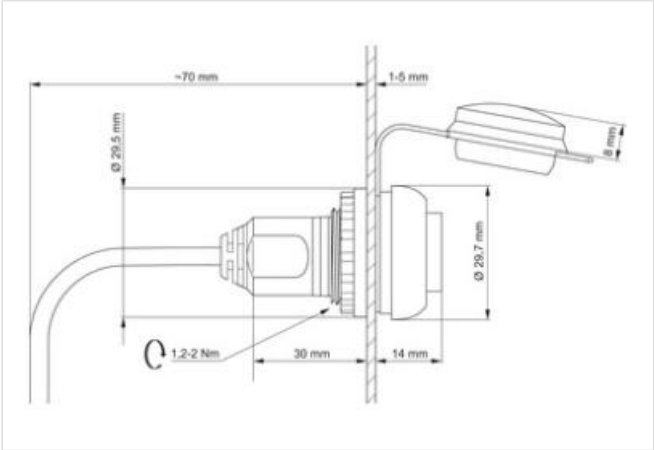

Product may differ from Image

**Commercial data**

ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
customs tariff number	85444290
GTIN	4048879857017
Packaging unit	1

Electrical data | Supply

Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA

Industrial communication

USB specification	3.0
-------------------	-----

Device protection

Shielded	yes
----------	-----

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state

Device protection | Mechanical

Mechanical endurance	1500 Cycles
----------------------	-------------

Mechanical data | Mounting data

Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	30 mm

Approvals

UL 50E	yes
--------	-----