

Modlight70 Pro connecting modul 8 pole M12

downward, Input 24VDC


Basic  
with M12 connection  
Outlet on the bottom  
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration



Product may differ from Image

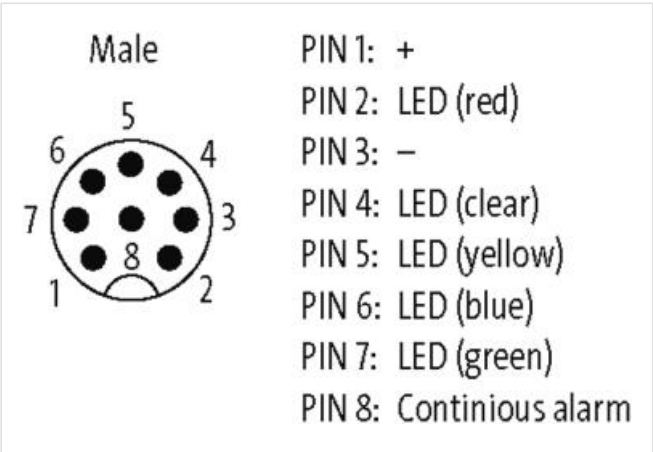

Commercial data	
ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
customs tariff number	85319000
GTIN	4048879758871
Packaging unit	1
Electrical data   Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Device protection   Electrical	
Degree of protection (EN IEC 60529)	IP65

Additional condition protection degree      inserted, locked

**Mechanical data | Material data**

Color housing      black

Material housing      Plastic

**Mechanical data | Mounting data**

Height      140 mm

Width      70 mm

Depth      70 mm

**Environmental characteristics | Climatic**

Operating temperature min.      -30 °C

Operating temperature max.      60 °C

**Connection type 1**

Mounting method      bayonet-locking