

Modlight70 Pro connecting modul 8 pole M12

side, Input 24VDC


Basic  
Outlet on the side  
with M12 connection  
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration



Product may differ from Image

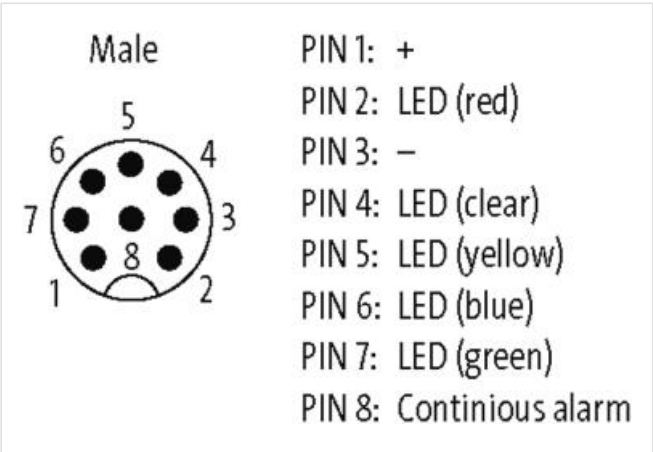

Commercial data	
ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
customs tariff number	85319000
GTIN	4048879758895
Packaging unit	1
Electrical data   Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Device protection   Electrical	
Degree of protection (EN IEC 60529)	IP65

Additional condition protection degree      inserted, locked

**Mechanical data | Material data**

Color housing	black
Material housing	Plastic

**Mechanical data | Mounting data**

Height	122 mm
Width	88 mm
Depth	70 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-30 °C
Operating temperature max.	60 °C

**Connection type 2**

Family construction form	M12
Gender	male
Coding	A
No. of poles	8
PIN 1	24 V DC / 0 V
PIN 2	LED-Modul RD
PIN 3	0 V / 24 V DC
PIN 4	LED-Modul CL
PIN 5	LED-Modul YE
PIN 6	LED-Modul BU
PIN 7	LED-Modul GN
PIN 8	Buzzer
Mounting method	bayonet-locking