

Modlight70 Pro connecting modul 8 pole M12

side, with magnet base


Basic  
with M12 connection  
with magnet base  
M12 (8-pole), sideways  
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration



Product may differ from Image

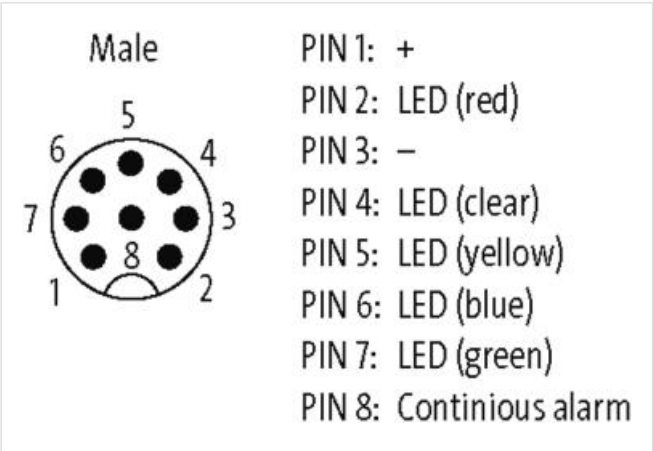

Commercial data

ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
customs tariff number	85319000
GTIN	4048879759601
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked
<b>Mechanical data</b>	
Adhesive force	290 N
<b>Mechanical data   Material data</b>	
Color housing	black
Material housing	Plastic
<b>Mechanical data   Mounting data</b>	
Height	135 mm
Width	88 mm
Depth	70 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-30 °C
Operating temperature max.	60 °C
<b>Connection type 2</b>	
Family construction form	M12
Gender	male
Coding	A
No. of poles	8
PIN 1	24 V DC / 0 V
PIN 2	LED-Modul RD
PIN 3	0 V / 24 V DC
PIN 4	LED-Modul CL
PIN 5	LED-Modul YE
PIN 6	LED-Modul BU
PIN 7	LED-Modul GN
PIN 8	Buzzer
Mounting method	bayonet-locking