



MODLINK MSDD FRAME DBL METALIC

with customized printing


Customized printing  
Frame: plastic PA black  
Lid: plastic, ABS gray  
Closure: 3 mm double bit  
with attachable rotation knob

Link to Product

Illustration

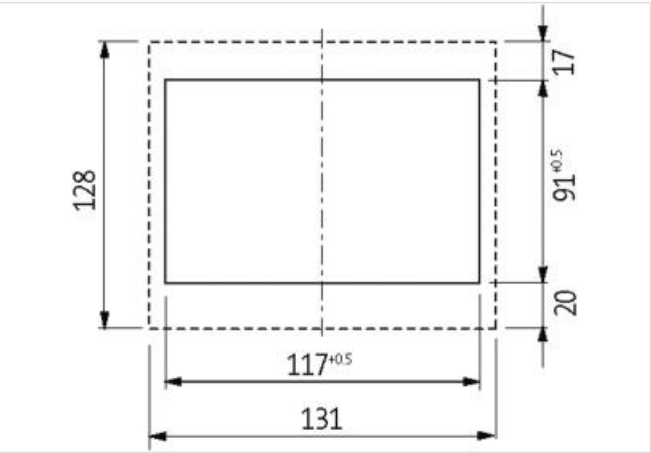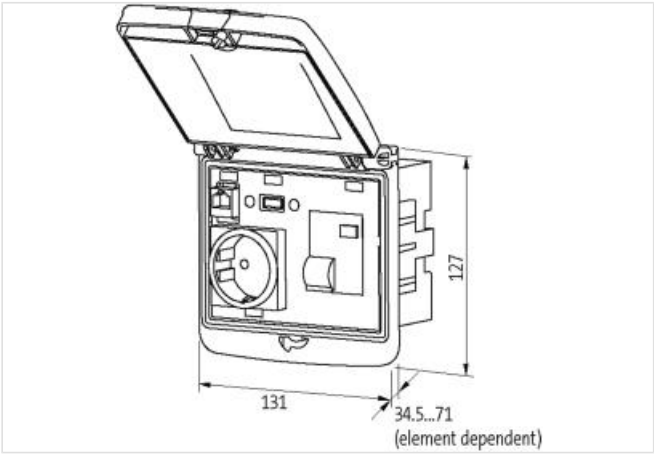

Product may differ from Image

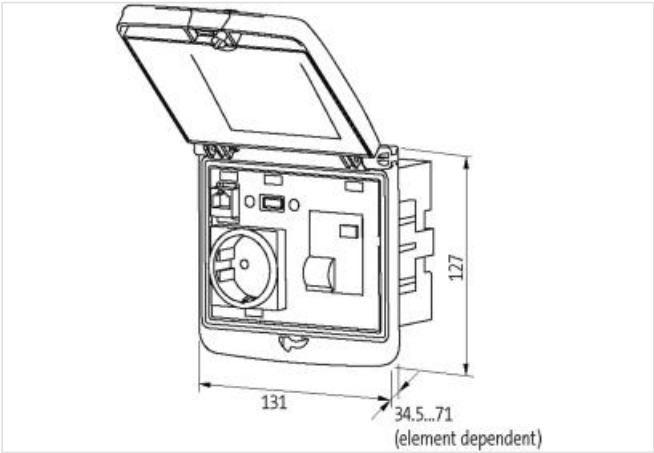

Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27189260
ECLASS-7.0	27189260
ECLASS-8.0	27189260
ECLASS-9.0	27182810

ECLASS-10.1	27182810
ECLASS-11.1	27182810
ECLASS-12.0	27182810
ETIM-5.0	EC002625
customs tariff number	85389099
GTIN	4048879689465
Packaging unit	1

**Mechanical data | Mounting data**

Height	127 mm
Width	131 mm
Depth	43 mm

**Frame**

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Color cover	metallic
Color housing	black
Material lid	ABS
Material housing	PA