



Bus terminating plug M12 male A-cod.

CUBE67


Cube67
Terminating resistor
Male
M12, 6-pole
A-coded
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

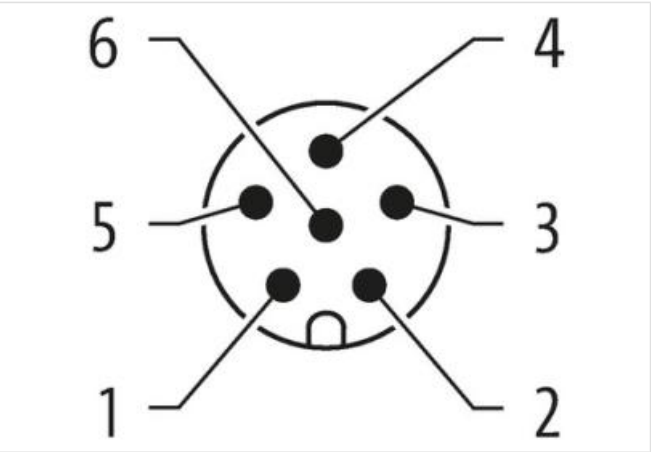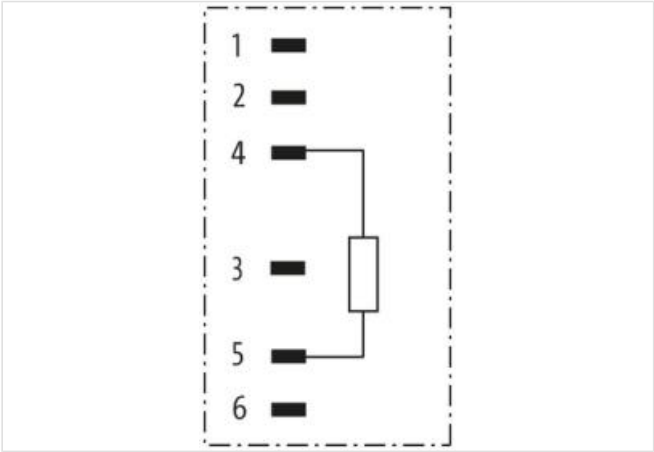

Product may differ from Image

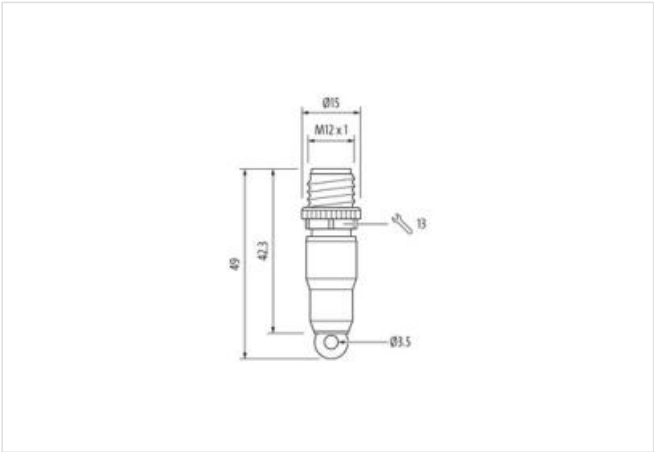

Side 1	
Tightening torque	0,6 Nm
Family construction form	M12
Degree of protection (EN IEC 60529)	IP67

Commercial data	
ECLASS-6.0	19070403
ECLASS-7.0	19070403
ECLASS-8.0	19070403
ECLASS-9.0	19070403
ECLASS-10.1	27440190
ECLASS-11.1	27440190
ECLASS-12.0	27440190
ETIM-5.0	EC001855
customs tariff number	85332100
GTIN	4048879196963
Packaging unit	1
Electrical data Supply	
Operating voltage DC max.	30 V
Operating voltage DC max. (UL-listed)	30 V
Current operating per contact max.	4 A
Device protection Electrical	
Additional condition protection degree	inserted, screwed
Mechanical data Mounting data	
Mounting method	inserted, screwed, Shaking protection
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C