

B6 Surface mounted h., high profile, IP65

Single locking lever m., side entry M25, p-cover


B6
Surface mounted housing (high)
Single locking lever
IP65
Technical data will be only guaranteed with Murrelektronik components.

Link to Product

Illustration



Product may differ from Image

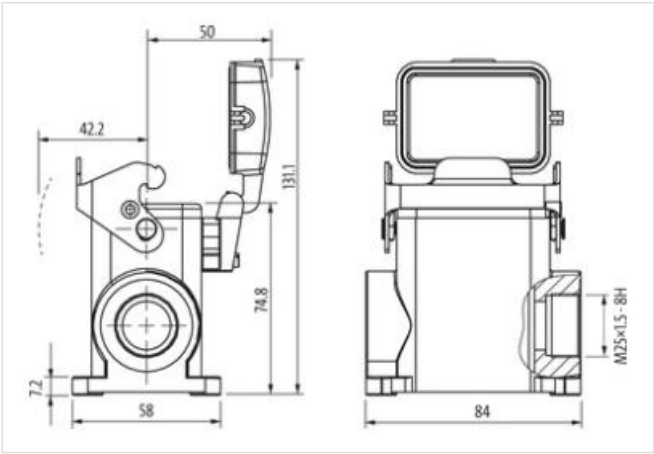

Commercial data

| | |
|-----------------------|---------------|
| ECLASS-6.0 | 27279221 |
| ECLASS-6.1 | 27261203 |
| ECLASS-7.0 | 27440202 |
| ECLASS-8.0 | 27440202 |
| ECLASS-9.0 | 27440202 |
| ECLASS-10.1 | 27440202 |
| ECLASS-11.1 | 27440202 |
| ECLASS-12.0 | 27440202 |
| ETIM-5.0 | EC000437 |
| customs tariff number | 85389099 |
| GTIN | 4048879696296 |
| Packaging unit | 1 |

Installation

Cable outlet laterally

Installation | Connection

| | |
|--------------------|-----|
| Mounting set | M25 |
| Mating cycles min. | 500 |

Device protection | Electrical

| | |
|--|---|
| Degree of protection (EN IEC 60529) | IP65 |
| Additional condition protection degree | inserted, locked, with screw connection |

Mechanical data

Housing type Surface mounted housing

Mechanical data | Material data

| | |
|---|----------------------|
| Coating housing | powder-coated |
| Coating locking | verzinkt |
| Material gasket | NBR |
| Material housing | Aluminum die casting |
| Material protective cover | Plastic |
| Locking material | Steel |
| Mechanical data Mounting data | |
| Size | B6 |
| Locking techniques | Single locking lever |
| Environmental characteristics Climatic | |
| Operating temperature min. | -40 °C |
| Operating temperature max. | 100 °C |
| Climatic category (EN IEC 60068-1) | 40/100/21 |