


B6 Surface mounted h., low profile, IP65

Single locking lever m., side entry M20, p-cover

B6
Surface mounted housing (low)
Single locking lever
IP65
Technical data will be only guaranteed with Murrelektronik components.

Link to Product

Illustration

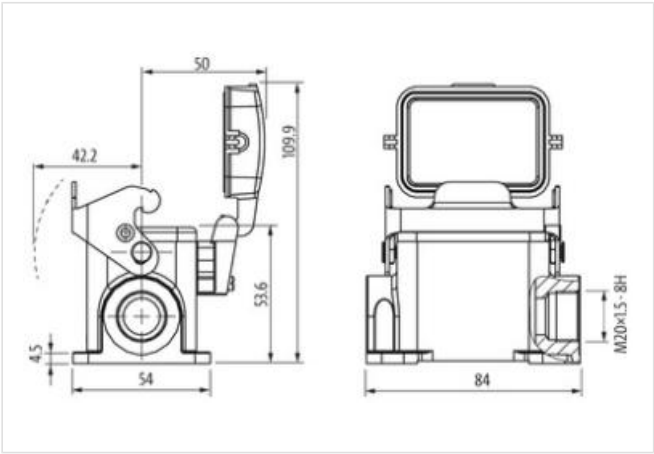

Product may differ from Image

Commercial data

ECLASS-6.0	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440102
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
customs tariff number	85389099
GTIN	4048879696272
Packaging unit	1

Installation

Cable outlet laterally

Installation | Connection

Mounting set	M20
Mating cycles min.	500

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection

Mechanical data

Housing type Surface mounted housing

Mechanical data | Material data

Coating housing powder-coated

Coating locking	verzinkt
Material gasket	NBR
Material housing	Aluminum die casting
Material protective cover	Plastic
Locking material	Steel

Mechanical data | Mounting data

Size	B6
Looking techniques	Single locking lever

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	100 °C
Climatic category (EN IEC 60068-1)	40/100/21