

**B10 Surface mounted h., low profile, IP65**

Single locking lever m., side entry M20, p-cover


B10  
Surface mounted housing (low)  
Single locking lever  
IP65  
Technical data will be only guaranteed with Murrelektronik components.

**[Link to Product](#)**

**Illustration**



Product may differ from Image

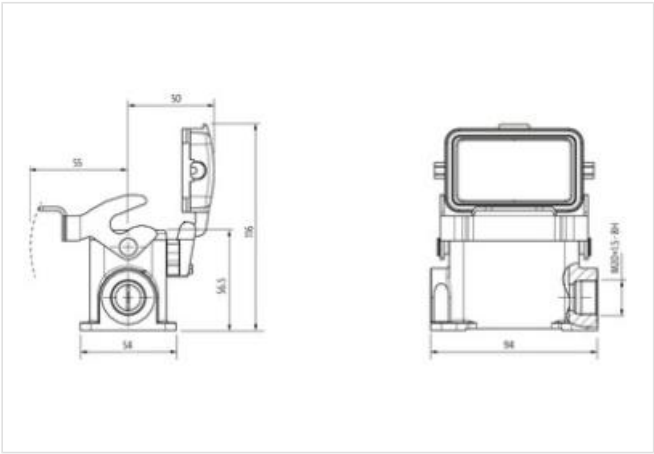

**Commercial data**

ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
customs tariff number	85389099
GTIN	4048879646253
Packaging unit	1

**Installation**

Cable outlet laterally

**Installation | Connection**

Mounting set	M20
Mating cycles min.	500

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection

**Mechanical data**

Housing type Surface mounted housing

**Mechanical data | Material data**

Coating housing	powder-coated
-----------------	---------------

Coating locking	verzinkt
-----------------	----------

Material gasket	NBR
-----------------	-----

Material housing	Aluminum die casting
------------------	----------------------

Material protective cover	Plastic
---------------------------	---------

Locking material	Steel
------------------	-------

**Mechanical data | Mounting data**

Size	B10
------	-----

Height	56,5 mm
--------	---------

Width	54 mm
-------	-------

Depth	94 mm
-------	-------

Looking techniques	Single locking lever
--------------------	----------------------

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	100 °C
----------------------------	--------

Climatic category (EN IEC 60068-1)	40/100/21
------------------------------------	-----------