

**B16 Surface mounted h., low profile, IP65**

Single locking lever m., side entry M25, p-cover

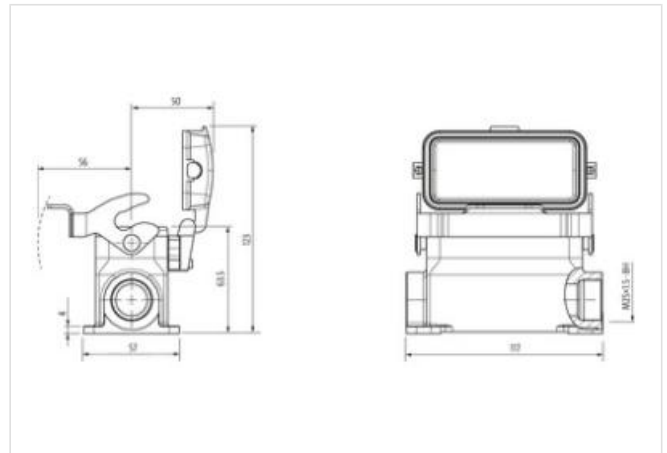
B16

Surface mounted housing (low)

Single locking lever

IP65

Technical data will be only guaranteed with Murrelektronik components.

**[Link to Product](#)****Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
customs tariff number	85389099
GTIN	4048879646550
Packaging unit	1

**Installation**

Cable outlet laterally

**Installation | Connection**

Mounting set	M25
Mating cycles min.	500

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection

**Mechanical data**

Housing type Surface mounted housing

**Mechanical data | Material data**

Coating housing	powder-coated
Coating locking	verzinkt
Material gasket	NBR
Material housing	Aluminum die casting
Material protective cover	Plastic
Locking material	Steel

**Mechanical data | Mounting data**

Size	B16
Height	63,5 mm
Width	57 mm
Depth	117 mm
Looking techniques	Single locking lever

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
Operating temperature max.	100 °C
Climatic category (EN IEC 60068-1)	40/100/21