

**A3 Hood, IP65**

Single locking lever, side entry M20

A3

Hood

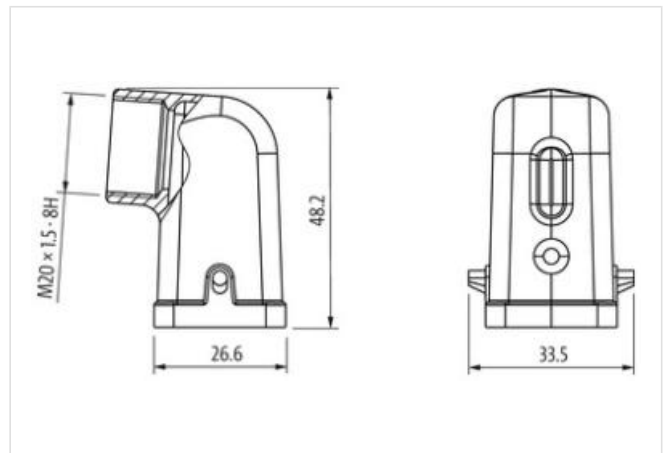
Single locking lever

IP65

Technical data will be only guaranteed with Murrelektronik components.

**[Link to Product](#)****Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0	27279221
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
customs tariff number	85389099
GTIN	4048879716802
Packaging unit	1

**Installation**

Cable outlet	laterally
--------------	-----------

**Installation | Connection**

Mounting set	M20
Mating cycles min.	500

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection

**Mechanical data**

Housing type	Hood
--------------	------

**Mechanical data | Material data**

Coating housing	powder-coated
-----------------	---------------

Coating locking	verzinkt
-----------------	----------

Material housing	Zinc die-casting
------------------	------------------

Locking material	Steel
------------------	-------

**Mechanical data | Mounting data**

Size	A3
------	----

Height	48,2 mm
--------	---------

Width	26,6 mm
-------	---------

Depth	33,4 mm
-------	---------

Looking techniques	Single locking lever
--------------------	----------------------

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	100 °C
----------------------------	--------

Climatic category (EN IEC 60068-1)	40/100/21
------------------------------------	-----------