


Single locking lever, top entry M20

**Link to Product**

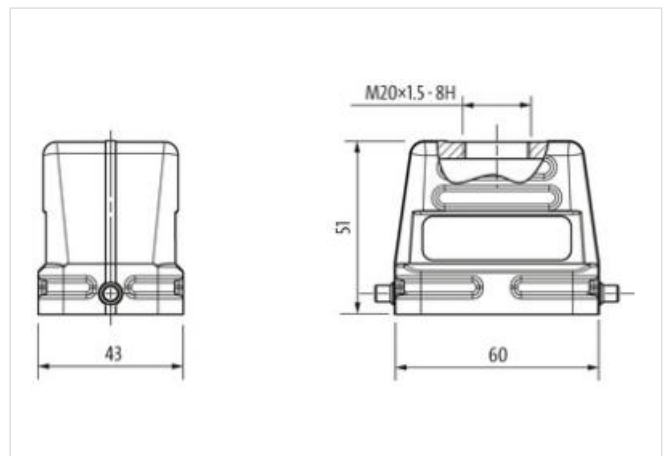

## Commercial data

## Installation

## Installation | Connection

Device protection | Electrical

### Mechanical data

Housing type	Hood
--------------	------

Mechanical data   Material data	
Coating housing	powder-coated
Coating locking	verzinkt
Material housing	Aluminum die casting
Locking material	Steel
Mechanical data   Mounting data	
Size	B6
Height	51 mm
Width	43 mm
Depth	60 mm
Locking techniques	Single locking lever
Environmental characteristics   Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	100 °C
Climatic category (EN IEC 60068-1)	40/100/21