


RJ45 module - female


Female  
RJ45  
Technical data will be only guaranteed with Murrelektronik components.  
The clip 70MH-ZZ100-0000000 is needed (2×)

Link to Product

Illustration

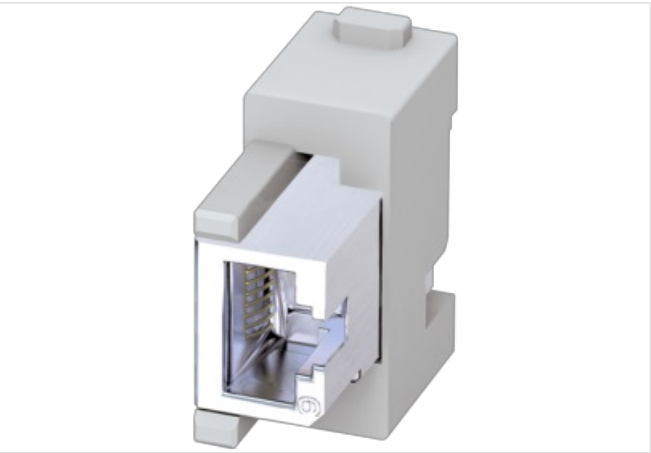

Product may differ from Image

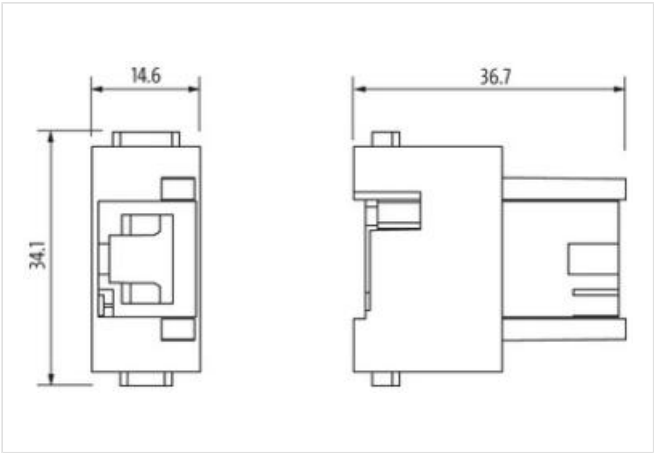

Commercial data	
ECLASS-6.0	27143424
ECLASS-6.1	27261204
ECLASS-7.0	27440204
ECLASS-8.0	27440204
ECLASS-9.0	27440204
ECLASS-10.1	27440204
ECLASS-11.1	27440204
ECLASS-12.0	27440204
ETIM-5.0	EC000437
customs tariff number	85366990
GTIN	4048879664066
Packaging unit	1
Electrical data   Supply	
Operating voltage AC	50 V
Operating voltage DC	50 V
Industrial communication	
Transfer parameters	CAT6A (IEC 60512-27-100:2008, TIA-568-C.2:2009)
Installation   Connection	
Gender	female
Mating cycles min.	500
Device protection   Electrical	

Pollution Degree	3
------------------	---

Rated surge voltage	0,8 kV
---------------------	--------

Overvoltage category (EN 60950-1)	III
-----------------------------------	-----

**Mechanical data | Material data**

Coating contact	gold plated
-----------------	-------------

Combustibility class (UL94)	V-0
-----------------------------	-----

Material housing	PC
------------------	----

Material contact	Cu
------------------	----

**Mechanical data | Mounting data**

Number of module slots	1
------------------------	---

Height	41 mm
--------	-------

Width	34,1 mm
-------	---------

Depth	14,6 mm
-------	---------

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	70 °C
----------------------------	-------