

## RJ45 module - female

Female


RJ45

Technical data will be only guaranteed with Murrelektronik components.


The clip 70MH-ZZ100-0000000 is needed (2×)

### [Link to Product](#)

#### Illustration

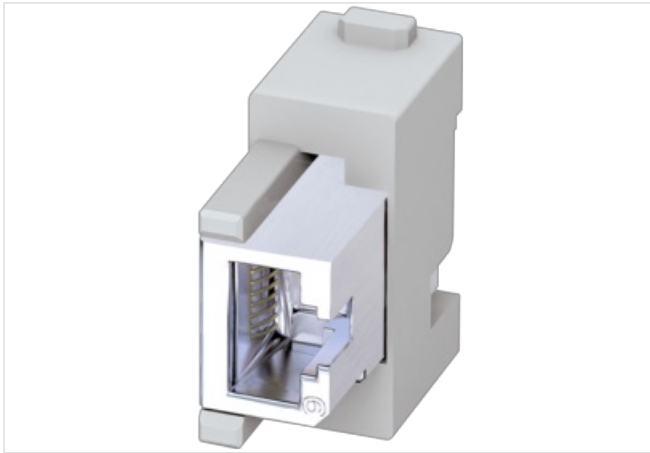

Product may differ from Image

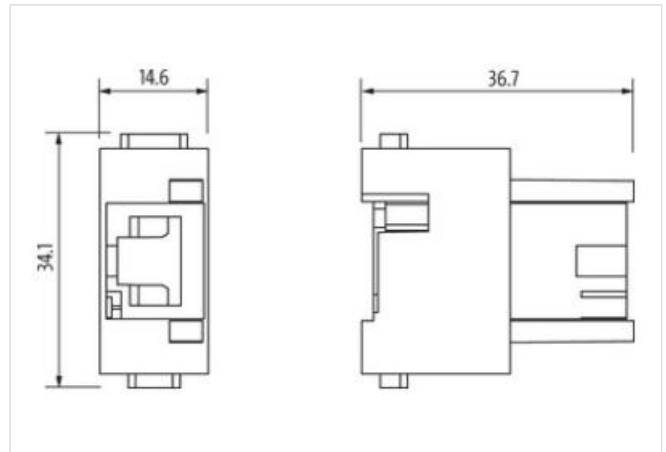

#### Technical Data

|                       |   |
|-----------------------|---|
| Operating voltage     | 50 V AC/DC                                      |
| Rated surge voltage   | 0.8 kV  |
| Transfer parameters   | CAT6A (IEC 60512-27-100:2008, TIA-568-C.2:2009) |
| Mating cycles         | min. 500  |
| Over voltage category | III   |

#### General data

|                            |                     |
|----------------------------|---------------------|
| Material (contact)         | Cu                  |
| Material (contact surface) | Au                  |
| Pollution Degree           | 3                   |
| Temperature range          | -40...+70 °C        |
| No. of module positions    | 1                   |
| Flammability class         | V-0 (acc. to UL 94) |
| Type                       | Female              |
| Material (module)          | PC                  |
| Dimensions H×W×D           | 41×34.1×14.6 mm     |

Product article number of manufacturer 70MH-MAM10-0000000