



Mini (7/8) 3 pole Tee, Male (Ext.)/2x Female

Red Housing


T-coupler 7/8" – 7/8", female/male
3-pole
Parallel circuit

[Link to Product](#)

Illustration

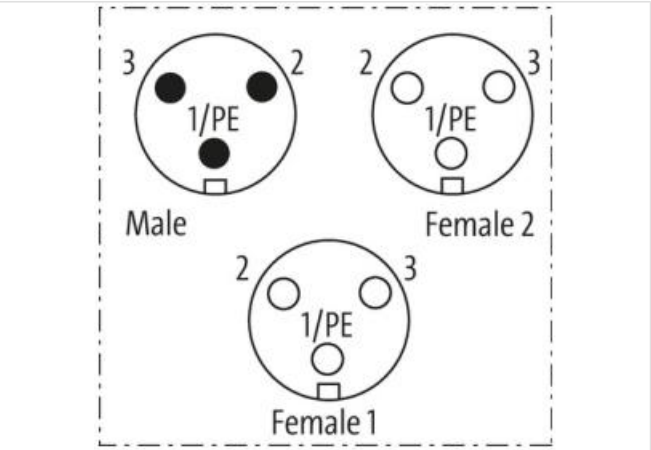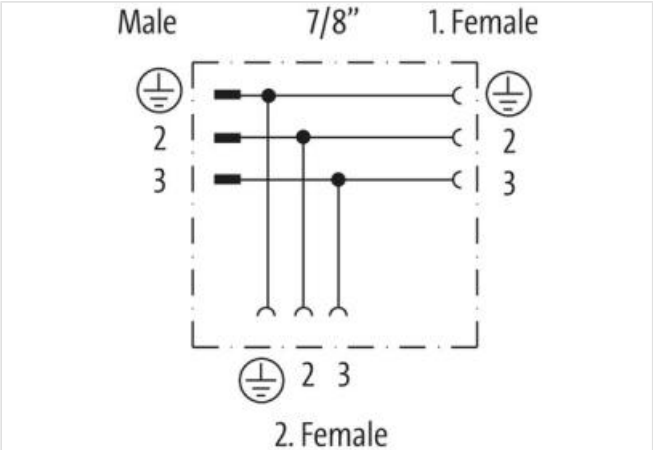

Product may differ from Image

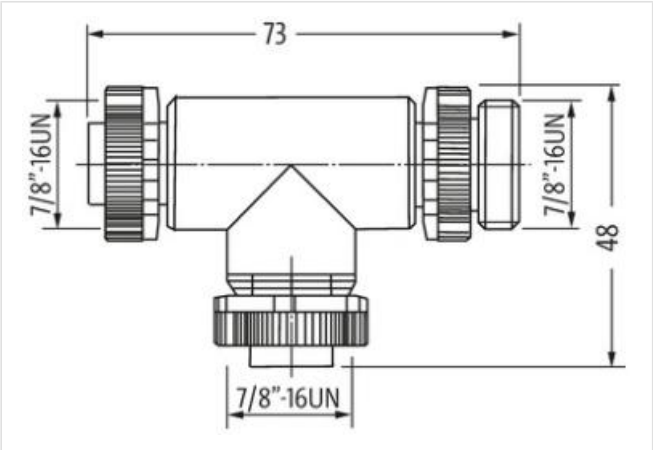

Commercial data	
ECLASS-6.1	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440106
ECLASS-10.1	27440106
ECLASS-11.1	27440106

ECLASS-12.0	27440106
customs tariff number	85366990
GTIN	4065909016039
Packaging unit	1
Electrical data Supply	
Operating voltage AC max.	600 V
Operating voltage DC max.	600 V
Current operating per contact max.	13 A
Installation Connection	
Mounting set	7/8"
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed
Pollution Degree	3
Mechanical data	
Contour for corrugated hose	without
Mechanical data Material data	
Coating locking	eloxiert
Material housing	PVC
Locking material	Aluminium
Mechanical data Mounting data	
Mounting method	Schraubgewinde
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	105 °C
Important installation notes	
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.
Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.