




Mini (7/8) 4 pole Tee, Male (Ext.)/2x Female

Yellow Housing

T-coupler 7/8" – 7/8", female/male  
4-pole  
Parallel circuit

Link to Product

Illustration

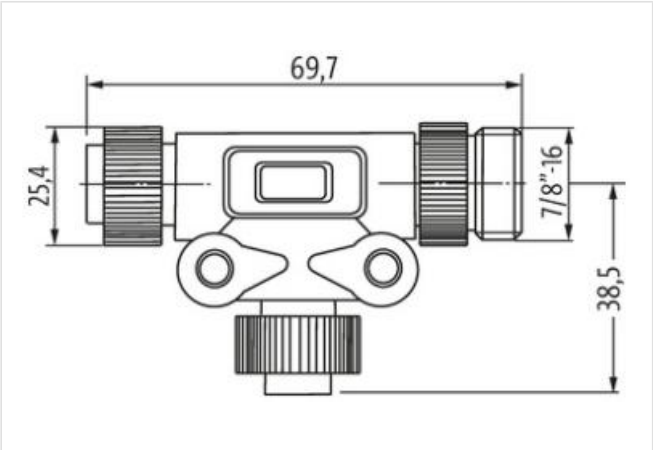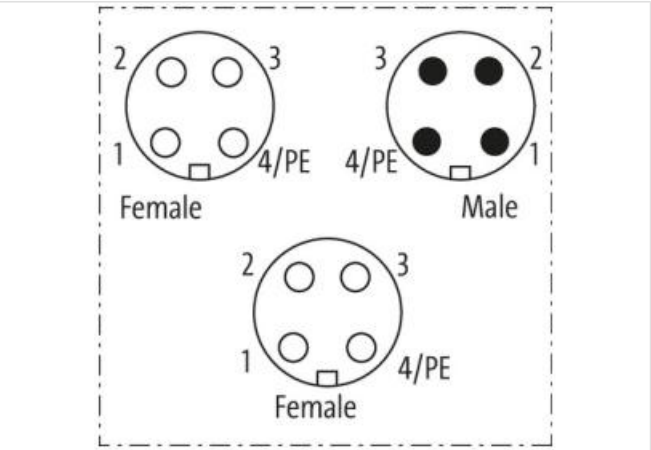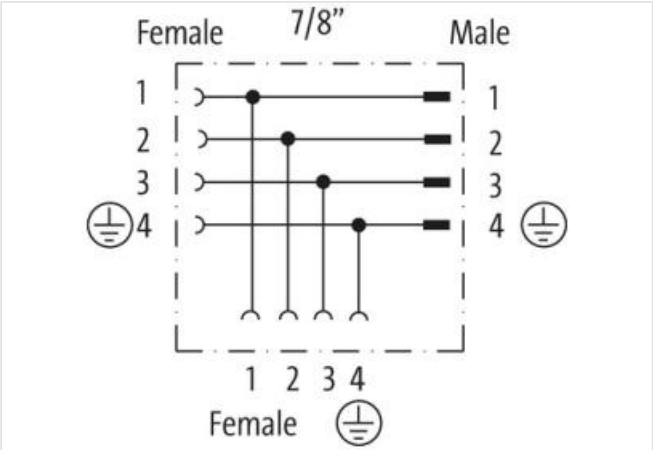

Product may differ from Image

Commercial data	
ECLASS-10.1	27440106
ECLASS-11.1	27440106
ECLASS-12.0	27440106
customs tariff number	85366990
GTIN	4065909016107
Packaging unit	1
Electrical data   Supply	
Operating voltage AC max.	600 V
Operating voltage DC max.	600 V
Current operating per contact max.	10 A
Installation   Connection	

Mounting set 7/8"

#### Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed
Pollution Degree	3

#### Mechanical data

Contour for corrugated hose	without
-----------------------------	---------

#### Mechanical data | Material data

Coating locking	eloxiert
Material housing	PVC
Locking material	Aluminium

#### Mechanical data | Mounting data

Mounting method	Schraubgewinde
-----------------	----------------

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	105 °C

#### Important installation notes

Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.
Note on bending radius	<b>Attention:</b> Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.