

**MICO IP67 electronic circuit protection, 4 Channels, 2A**

IN: 24 V DC OUT: 24 V DC / 2 A CL2 / Expandable

MICO67 4.2 CL2

4 × M12, A-coded NEC CL2, (2 A)

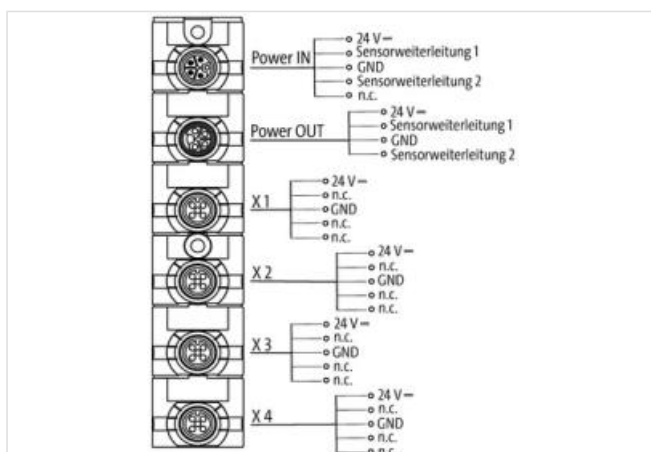
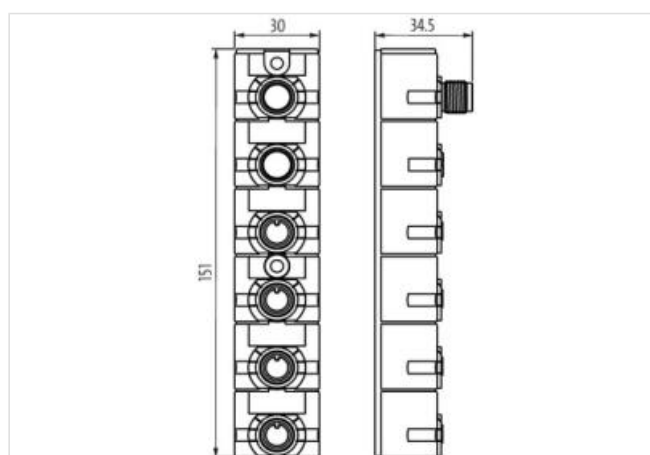
Voltage IN and transmission via M12, L-coded (16 A)

24 V/16 A

24 V/2 A

LED port diagnostic

Limitation of the 4 voltage taps to 2 A (M12, A-coded)

[Link to Product](#)
**Illustration**


Product may differ from Image


**Commercial data**

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27371802      |
| customs tariff number | 85363010      |
| GTIN                  | 4048879852272 |

Packaging unit 1

**Device protection | Electrical**

Degree of protection (EN IEC 60529) IP65, IP67

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -25 °C |
| Operating temperature max. | 45 °C  |
| Storage temperature min.   | -25 °C |
| Storage temperature max.   | 70 °C  |