



MICO FUSE 250 FUSE HOLDER 5X20MM 8 CHANNELS

IN: 250V AC/DC OUT: 250V AC/DC / 6A AC/DC

MICO FUSE 250
8 channels
Total current: max. 40 A

[Link to Product](#)

Illustration

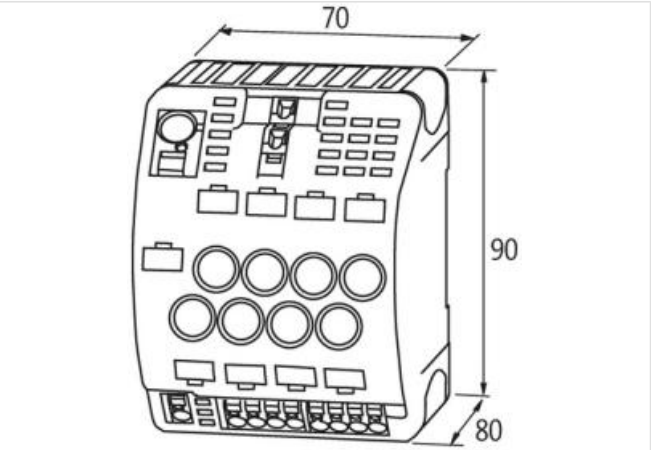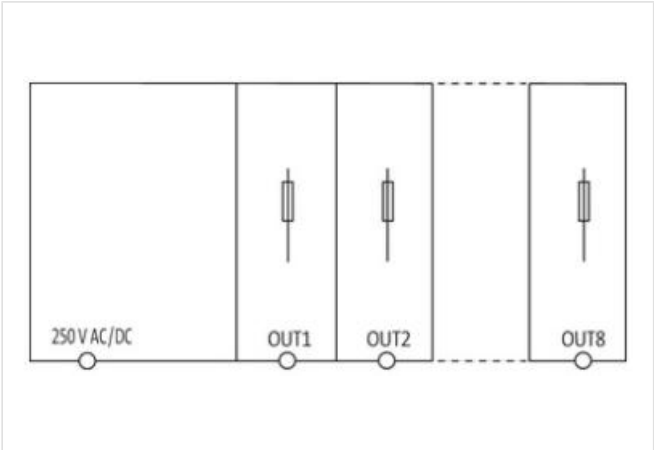

Product may differ from Image



| Commercial data | |
|-----------------|----------|
| ECLASS-6.0 | 27371802 |
| ECLASS-6.1 | 27142107 |
| ECLASS-7.0 | 27142121 |
| ECLASS-8.0 | 27142121 |
| ECLASS-9.0 | 27142121 |
| ECLASS-10.1 | 27142121 |

| | |
|-----------------------|---------------|
| ECLASS-11.1 | 27142121 |
| ECLASS-12.0 | 27142121 |
| ETIM-5.0 | EC001440 |
| customs tariff number | 85363030 |
| GTIN | 4048879335270 |
| Packaging unit | 1 |

Electrical data | Supply

| | |
|---------------------------|-------|
| Operating voltage AC max. | 250 V |
| Operating voltage DC max. | 250 V |
| Operating current max. | 6 A |
| Total current max. | 40 A |

Installation

| | |
|---------------------------------------|---------------------|
| Connection cross-section inputs max. | 16 mm ² |
| Connection cross-section outputs min. | 0,5 mm ² |
| Connection cross-section outputs max. | 4 mm ² |

Mechanical data | Mounting data

| | |
|----------------------------|--------------------------------|
| Mounting method | geschnappt |
| Suitable for mounting type | Mounting rail TH35, (EN 60715) |
| Height | 90 mm |
| Width | 70 mm |
| Depth | 80 mm |

Environmental characteristics | Climatic

| | |
|----------------------------|--------|
| Operating temperature min. | -25 °C |
| Operating temperature max. | 55 °C |
| Derating from | 40 °C |

Connection type 3

| | |
|--------------------------|---------------------------|
| Connection | Spring clamp terminals FK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | green |
| No. of poles | 1 |
| PIN 1 | In |
| Connection | Spring clamp terminals FK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | green |
| No. of poles | 4 |
| PIN 1 | Out 1 |
| PIN 2 | Out 2 |
| PIN 3 | Out 3 |
| PIN 4 | Out 4 |
| Connection | Spring clamp terminals FK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | green |
| No. of poles | 4 |
| PIN 1 | Out 5 |
| PIN 2 | Out 6 |
| PIN 3 | Out 7 |
| PIN 4 | Out 8 |