

**MODL. VARIO insert for fixed housing type B**

6/4 shut-off, nickel plated brass


Insert - stationary housing  
Brass, nickel plated  
with shut-off  
AD6

[Link to Product](#)

Illustration



Product may differ from Image

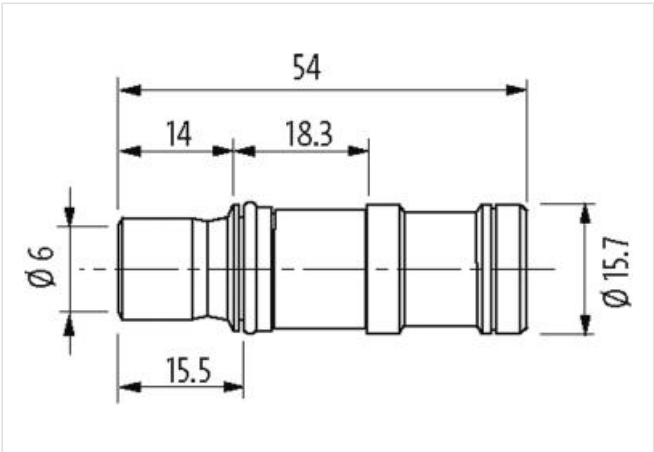

Commercial data

ECLASS-6.0	27260702
ECLASS-6.1	27260708
ECLASS-7.0	27440312
ECLASS-8.0	27440312
ECLASS-9.0	27440312
ECLASS-10.1	27440312
ECLASS-11.1	27440312
ECLASS-12.0	27440312
ETIM-5.0	EC002641
customs tariff number	74198090
GTIN	4048879573764
Packaging unit	1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67, IP68
Degree of protection (ISO 20653:2013)	IP66K, IP69K
Additional condition protection degree	inserted, screwed

Mechanical data

Barrier	with shut-off
Operating pressure min.	0 bar
Operating pressure max.	16 bar

Mechanical data | Material data

Coating housing	nickel plated
Material gasket	FPM
Material housing	Brass

**Mechanical data | Mounting data**

Outer diameter hose 6 mm

**Environmental characteristics | Climatic**

Operating temperature min. -20 °C

---

Operating temperature max. 120 °C