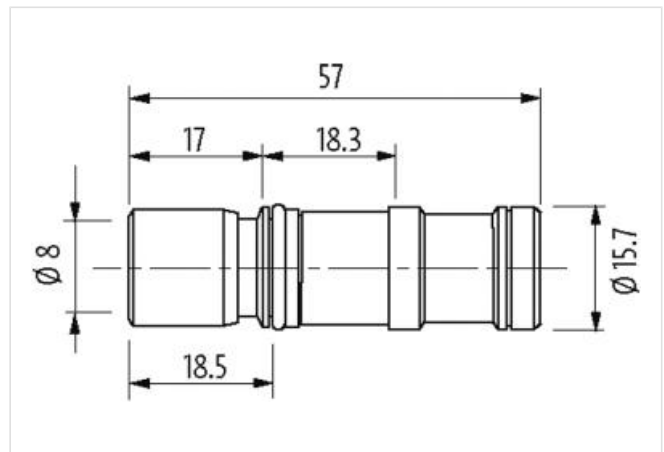


**MODL. VARIO insert for fixed housing type B**

8/6 shut-off, nickel plated brass

Insert - stationary housing  
 Brass, nickel plated  
 with shut-off  
 AD8

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0	27260702
ECLASS-6.1	27260708
ECLASS-7.0	27440312
ECLASS-8.0	27440312
ECLASS-9.0	27440312
ECLASS-10.1	27440312
ECLASS-11.1	27440312
ECLASS-12.0	27440312
ETIM-5.0	EC002641
customs tariff number	74198090
GTIN	4048879573849
Packaging unit	1

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP65, IP67, IP68
Degree of protection (ISO 20653:2013)	IP66K, IP69K
Additional condition protection degree	inserted, screwed

**Mechanical data**

Barrier	with shut-off
Operating pressure min.	0 bar
Operating pressure max.	16 bar

**Mechanical data | Material data**

Coating housing	nickel plated
Material gasket	FPM
Material housing	Brass

**Mechanical data | Mounting data**

Outer diameter hose 8 mm

**Environmental characteristics | Climatic**

Operating temperature min. -20 °C

---

Operating temperature max. 120 °C